


# Technical data sheet

## T piece adapter WDK 40060

Item number: 6113310

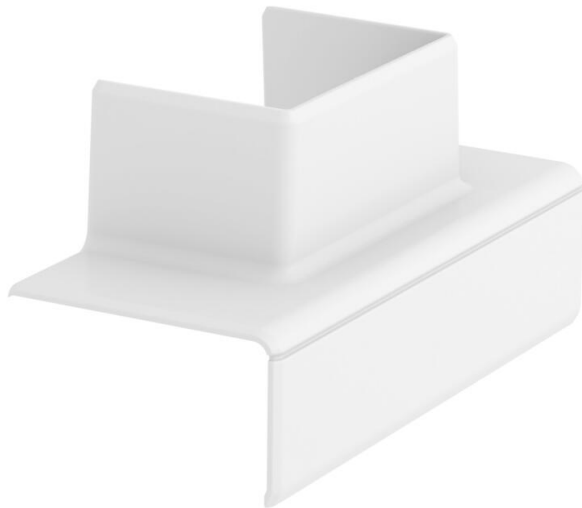

T-piece adapter to create a 90° junction from the system size Rapid 45-2 53100 and 53165 on a cable trunking WDK40060.



Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Item number                        | 6113310                                      |
| Type                               | GK-TA WDK 1RW                                |
| Description 1                      | T piece adaptor                              |
| Description 2                      | 100 and 165 to WDK 40060                     |
| Manufacturer                       | OBO                                          |
| Dimension                          | 120x62x56                                    |
| Colour                             | Pure white; RAL 9010                         |
| Material                           | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit                | 1                                            |
| Unit of quantity                   | Piece                                        |
| Weight                             | 3.002 kg                                     |
| Weight unit                        | kg/100 pc.                                   |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,1904 kg CO2e / 1 Piece                     |


# Technical data sheet

## T piece adapter WDK 40060

Item number: 6113310



### Dimensions

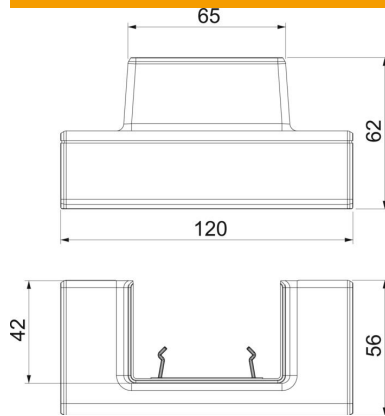

|        |         |
|--------|---------|
| Length | 120 mm  |
| Width  | 62 mm   |
| Height | 55.5 mm |

### Technical data

|                                   |              |
|-----------------------------------|--------------|
| Number of covers                  | 0            |
| Version for                       | Hood fitting |
| for duct width                    | 100 mm       |
| for trunking height               | 53 mm        |
| Halogen-free                      | yes          |
| Cable retaining clip              | no           |
| Duct connector                    | no           |
| Cover mounting type               | Cross-over   |
| Mounting perforation in base      | no           |
| Cover width                       | 0 mm         |
| Cover width 2                     | 0 mm         |
| Cover width 3                     | 0 mm         |
| ROHS-conformant                   | yes          |
| Protection rating                 | IP40         |
| Protective film                   | no           |
| Protection rating IK code         | IK08         |
| Symmetrical                       | no           |
| Permitted temperature range, max. | 60 °C        |
| Permitted temperature range, min. | -15 °C       |