


Technical data sheet

Cover

Item number: 6114162

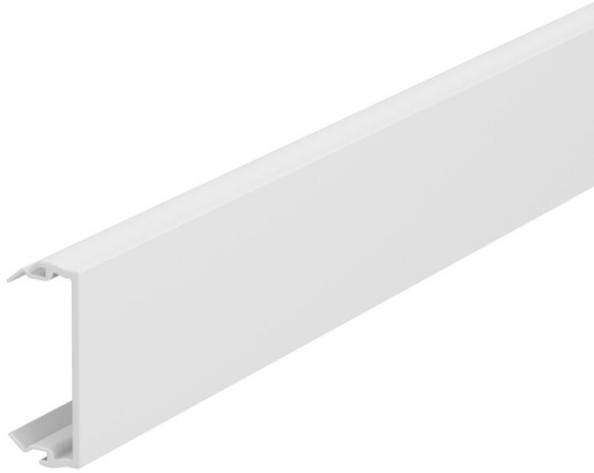

Wall and ceiling trunking, halogen-free, consisting of base and cover for mounting directly on the wall.
During installation, ensure that only halogen-free accessories and fastening materials are used.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6114162
Type	GKH-OT45RW
Description 1	Cover halogen-free
Description 2	Rapid 45-2
Manufacturer	OBO
Dimension	2000x45
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Metre
Weight	15.9 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,1474 kg CO2e / 1 Meter


Technical data sheet

Cover

Item number: 6114162



Dimensions

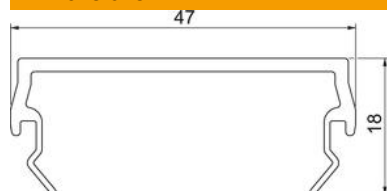

Length	2,000 mm
Width	45 mm

Technical data

Version for	Smooth
Halogen-free	no
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP40
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C