

Technical data sheet

Trunking cover, smooth

Item number: 6114210



Smooth trunking cover made of halogen-free PC/ABS, for closing device installation trunking with 80 mm system opening.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6114210
Type	GKH-OTGRW
Description 1	Cover, halogen-free
Manufacturer	OBO
Dimension	80x2000
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Metre
Weight	22 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,2707 kg CO2e / 1 Meter


Technical data sheet

Trunking cover, smooth

Item number: 6114210



Dimensions

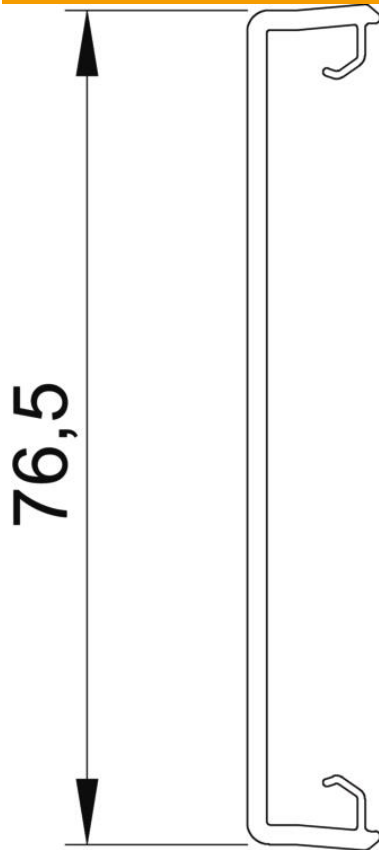

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-15 °C