

# Technical data sheet

## Partition GKH-TW70

Item number: 6114290



Partition made of halogen-free PC/ABS for mounting in Rapid 80 GKH (GA) device installation trunking or ISS service poles for installing cables of different voltage levels.



Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Item number                        | 6114290                                      |
| Type                               | GKH-TW70                                     |
| Description 1                      | Partition, halogen-free                      |
| Description 2                      | for GKH                                      |
| Manufacturer                       | OBO                                          |
| Dimension                          | 70x2000                                      |
| Colour                             | Pure white; RAL 9010                         |
| Material                           | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit                | 2                                            |
| Unit of quantity                   | Metre                                        |
| Weight                             | 14 kg                                        |
| Weight unit                        | kg/100 m                                     |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,7748 kg CO2e / 1 Meter                     |


# Technical data sheet

## Partition GKH-TW70

Item number: 6114290



### Dimensions

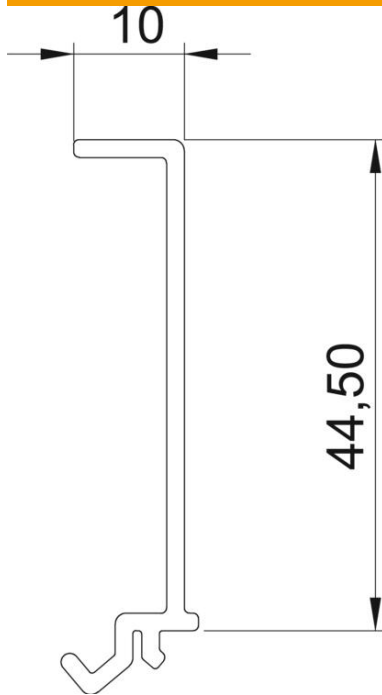

|        |          |
|--------|----------|
| Length | 2,000 mm |
| Width  | 44.5 mm  |
| Height | 10 mm    |

### Technical data

|                                   |         |
|-----------------------------------|---------|
| Version for                       | Single  |
| Fastening type                    | Plug-in |
| Suitable for duct depth           | 70      |
| Halogen-free                      | yes     |
| ROHS-conformant                   | yes     |
| Protection rating                 | IP30    |
| Protection rating IK code         | IK08    |
| Permitted temperature range, max. | 90 °C   |
| Permitted temperature range, min. | -15 °C  |