


Technical data sheet

Cover

Item number: 6116108

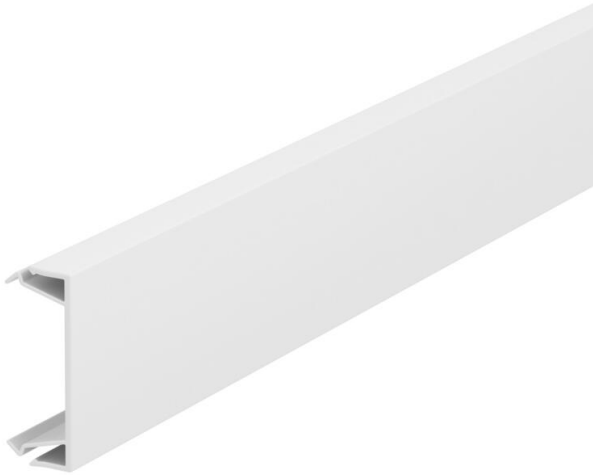

Trunking cover for closing the Rapid 45 device installation trunking.



PVC Polyvinylchloride

Master data	
Item number	6116108
Type	GEK-KOT45
Description 1	Cover
Description 2	Rapid 45
Manufacturer	OBO
Dimension	45x2000mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	18.6 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,4061 kg CO2e / 1 Meter

Technical data sheet


Cover

Item number: 6116108



Dimensions

Length	2,000 mm
Width	45 mm

 

Technical data

Version for	Smooth
Halogen-free	no
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C