

Technical data sheet

Joint cover

Item number: 6116152



Joint cover for the covers of the Rapid 45 device installation trunking to hide cut edges and provide tidy connection to installed Modul 45 devices.



PVC Polyvinylchloride

Master data

Item number	6116152
Type	GEK-KSOT45
Description 1	Joint cover
Description 2	for cover
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	6
Unit of quantity	Piece
Weight	0.284 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0083 kg CO2e / 1 Piece


Technical data sheet

Joint cover

Item number: 6116152



Dimensions

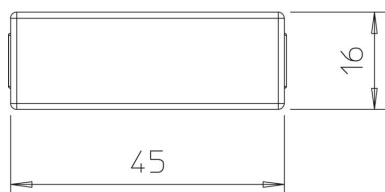

Technical data

Halogen-free	yes
ROHS-conformant	yes
Protection rating	IP40
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C