


Technical data sheet

Trunking connector and joint cover

Item number: 6116163



Joint cover for smooth connection of trunking segments.

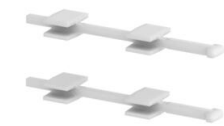

PVC Polyvinylchloride

Master data

Item number	6116163
Type	GEK-KS45-3
Description 1	Joint cover
Description 2	for GEK-K53160-3, 3-compart.
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	6
Unit of quantity	Piece
Weight	1.324 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0406 kg CO2e / 1 Piece


Technical data sheet

Trunking connector and joint cover

Item number: 6116163



Dimensions

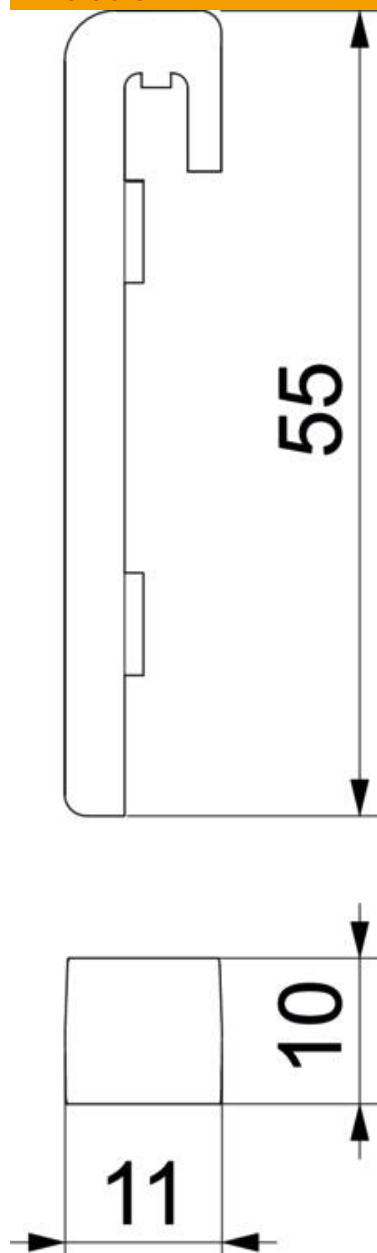

Technical data sheet

Trunking connector and joint cover

Item number: 6116163



Technical data

Version for	Trunking cut cover
Fastening type	Miscellaneous
Shape	Universal
for duct width	165 mm
for trunking height	53 mm
Halogen-free	no
Cover width	45 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C