


Technical data sheet

Joint connector

Item number: 6116752

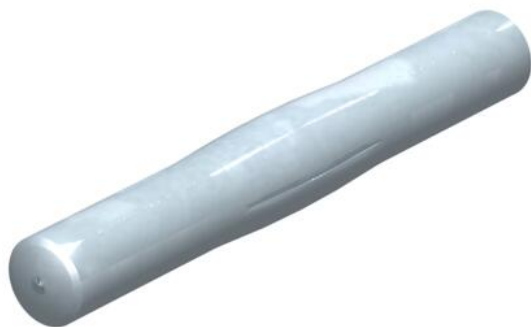

Joint connectors as notched pins for direct joint-to-joint connection of the trunking bases without joint cover. Suitable for aluminium device installation trunking of the Rapid 80 and Rapid 45-2 series and GAD design trunking for system use for cable routing and/or with Modul45 connect. Also compatible with the BK 1874 floor trunking.

 


St	Steel
VZ	galvanised

Master data

Item number	6116752
Type	GEK-AKU45
Description 1	Joint connector
Description 2	Rapid 45
Manufacturer	OBO
Dimension	3x24mm
Colour	zinc
Material	Steel
Surface	galvanised
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.135 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0127 kg CO2e / 1 Piece

Dimensions



Length	24 mm
Width	3 mm
Height	3 mm

Technical data sheet

Joint connector

Item number: 6116752



Technical data

Version for	Universal
Type	Pin
Halogen-free	yes
With equipotential bonding	yes