

Technical data sheet

0° socket, Switzerland, single

Item number: 6117200



Socket, single 0°, to Swiss standard (SEV), with screwless terminals, 2-pin, 10 A, 250 V~, type 13, with connection terminals to IEC 60884-1.
For installation in Rapid 45 ducts, device installation ducts, installation columns, underfloor systems and Deskboxes.



PC Polycarbonate

Master data

Item number	6117200
Type	SKS-CH0 RW1
Description 1	Socket Swiss standard
Manufacturer	OBO
Dimension	250V, 10A
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	3.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,018 kg CO2e / 1 Piece


Technical data sheet

0° socket, Switzerland, single

Item number: 6117200



Dimensions

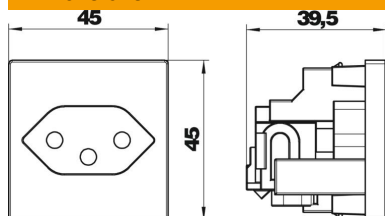

Width	45 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Number of units	1
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	Swiss Standard, Type 13
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	no
Error current protection	no
For more difficult conditions (according to VDE)	no
Power reserve	no
Halogen-free	no
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	10 A
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	39.5 mm
Transparent	no
Rotated central insert	no
Surge protection	no