

Technical data sheet

0° socket, Denmark, single, IT-encoded

Item number: 6117203



Socket, single 0°, to Danish standard, encoded for IT power circuit, with screw terminals, 2-pin, 16 A 250 V~, with connection terminals to IEC 60884-1. For installation in Rapid 45 trunking, device installation trunking, service poles, underfloor systems and desk boxes.



PC Polycarbonate

Master data

Item number	6117203
Type	SKS-DKE0 RW1
Description 1	Socket, Danish version
Description 2	for IT power circuit
Manufacturer	OBO
Dimension	250V, 10/16A
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	12
Unit of quantity	Piece
Weight	3.05 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0097 kg CO2e / 1 Piece


Technical data sheet

0° socket, Denmark, single, IT-encoded


Item number: 6117203



Dimensions

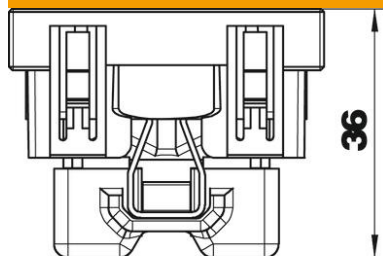

Width	45 mm
Height	45 mm

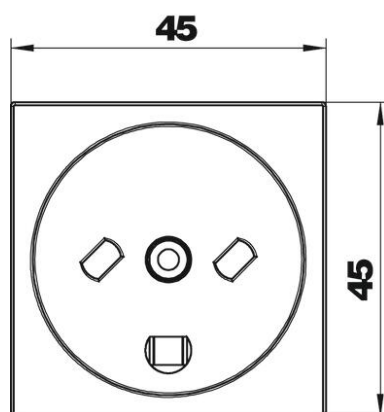

Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	Danish norm (earthing pin)
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	no
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	no
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no

Technical data sheet

0° socket, Denmark, single, IT-encoded

Item number: 6117203



Technical data

With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
ROHS-conformant	yes
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	36 mm
Transparent	no
Rotated central insert	no
Surge protection	no