

Technical data sheet

IKR6 installation unit, for 2 part units

Item number: 6119319



Installation unit to accept protective units such as miniature circuit breakers of FI protection switches up to 2 PUs, suitable for installation in Rapid 80 device installation trunking systems and ISS service poles.

Installation unit, consisting of:

- Accessory mounting box, triple, type 71GD9-2
- Cover, incl. PVC support clamp for 2 PUs, colour: see table
- Cover frame AR45, triple, without labelling panel, colour: pure white
For installation in Rapid 80 device installation trunking and ISS service poles.

PC Polycarbonate

Master data

Item number	6119319
Type	IKR-6 RW
Description 1	Flush-mount unit
Description 2	f. device install. Duct, 2 PUs
Manufacturer	OBO
Dimension	84x185x95mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	19 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8045 kg CO2e / 1 Piece


Technical data sheet

IKR6 installation unit, for 2 part units

Item number: 6119319



Dimensions

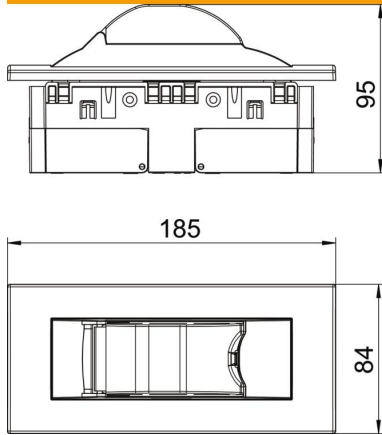

Length	185 mm
Width	84 mm
Height	95 mm

Technical data

Number of units	2
Number of rows	1
Surface version	Matt
DIN rail	yes
Suitable for duct depth	80
Halogen-free	no
With mounting plate	yes
Mounting type	Device installation duct
Mounting type	Device installation duct
ROHS-conformant	yes