

Technical data sheet

Flush-mount unit for data technology, type RM

Item number: 6119490



Installation unit to accommodate two type RM data technology modules, suitable for installation in Rapid 80 device installation trunking systems and ISS service poles. The type RM data technology support is suitable for accepting the following data connection modules: OBO (type): ASM-C5, ASM-C5 G, ASM-C6 and ASM-C6 G; R&M: Cat. 5 and Cat. 6 modules without support plate.

Installation unit, consisting of:

- Mounting support, single, type 71MT1 45
- Data technology support, straight outlet, type DTG-2RM, colour: see table
- Cover frame AR45, single, without labelling panel, colour: pure white

For installation in Rapid 80 device installation trunking and ISS service poles.

PC Polycarbonate

Master data

Item number	6119490
Type	DTE-RW G2RM1
Description 1	Inst.unit, data technology
Description 2	f.2 connection modules type RM
Manufacturer	OBO
Dimension	84x84x59mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4299 kg CO2e / 1 Piece


Technical data sheet

Flush-mount unit for data technology, type RM

Item number: 6119490



Dimensions

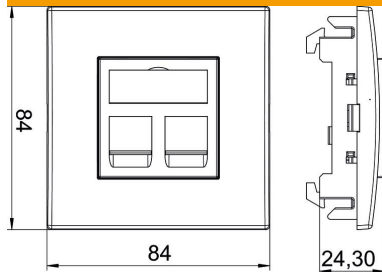

Length	84 mm
Width	84 mm

Technical data

Surface version	Matt
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	yes
Mounting type	Device installation duct
ROHS-conformant	yes
Protection rating	IP20
Depth	24.3 mm
Support ring	no
Transparent	no
Use	Modular jack
Strain relief option	no
Combination	Basic element with full cover plate