

Technical data sheet

Flush-mount unit for data technology, type A

Item number: 6119494



Installation unit to accommodate two type A data technology modules, suitable for installation in Rapid 80 device installation trunking systems and ISS service poles. The type A data technology support is suitable for accepting the following data connection modules: AMP TYCO (without dust protection cap): SL Series 110Connect and SL Series Toolless; Brand-Rex: modules with item numbers ending in ...JAKS000CR and ...JAKU002; Nexans: LANmark RJ45 with blue adapter clip, LANmark GG45 with metal clip.

Installation unit, consisting of:

- Mounting support, single, type 71MT1 45
 - Data technology support, straight outlet, type DTG-2A, colour: see table
 - Cover frame AR45, single, without labelling panel, colour: pure white
- For installation in Rapid 80 device installation trunking and ISS service poles.

PC Polycarbonate

Master data

Item number	6119494
Type	DTE-RW G2A1
Description 1	Inst.unit, data technology
Description 2	f.2 connection modules type A
Manufacturer	OBO
Dimension	84x84x59mm
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4201 kg CO2e / 1 Piece


Technical data sheet

Flush-mount unit for data technology, type A

Item number: 6119494



Dimensions

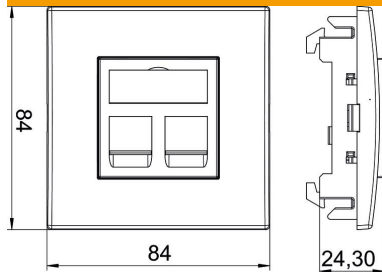

Length	84 mm
Width	84 mm

Technical data

Surface version	Matt
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	yes
Mounting type	Device installation duct
ROHS-conformant	yes
Protection rating	IP20
Depth	24.3 mm
Support ring	no
Transparent	no
Use	Modular jack
Strain relief option	no
Combination	Basic element with full cover plate