

Technical data sheet

0° socket, British Standard, single

Item number: 6120722



Socket, single 0°, British Standard, conforms to BS 1363, with increased touch protection, with screw terminals, 2-pin, 13 A, 250 V~.



PC

Polycarbonate

Master data		
	Item number	6120722
	Type	STD-BS0 RW1
	Description 1	Socket 0°, single
	Description 2	British Standard
	Manufacturer	OBO
	Dimension	250V, 13A
	Colour	Pure white; RAL 9010
	Material	Polycarbonate
	Smallest sales unit	1
	Unit of quantity	Piece
	Weight	4 kg
	Weight unit	kg/100 pc.
	CO2 Footprint (GWP) Cradle-to-Gate	0,018 kg CO2e / 1 Piece


Technical data sheet

0° socket, British Standard, single

Item number: 6120722



Dimensions

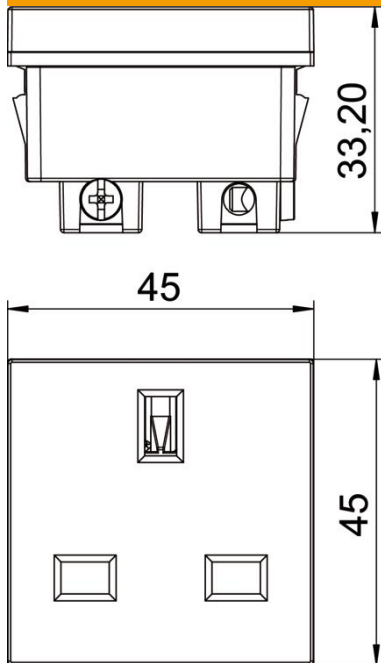

Width	45 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screw terminal
Number of units	1
Number of modules (for modular construction)	0
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Matt
Version for	British Standard
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Insulated installation	no
Hinged cover	no
Coding	no

Technical data sheet

0° socket, British Standard, single

Item number: 6120722



Technical data

Warning light	no
With on/off switch	no
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	13 A
ROHS-conformant	yes
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	33.2 mm
Transparent	no
Rotated central insert	no
Surge protection	no