

Technical data sheet

0° socket with switch, British Standard, single

Item number: 6120724



Socket, single 0°, with switch, British Standard, conforms to BS 1363, with increased touch protection, with screw terminals, 2-pin, 13 A, 250 V~.



PC Polycarbonate

Master data	
Item number	6120724
Type	STD-BS0G RW1.5
Description 1	Socket 0°, single
Description 2	British Standard, with switch
Manufacturer	OBO
Dimension	250V, 13A
Colour	Pure white; RAL 9010
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0359 kg CO2e / 1 Piece


Technical data sheet

0° socket with switch, British Standard, single

Item number: 6120724



Dimensions

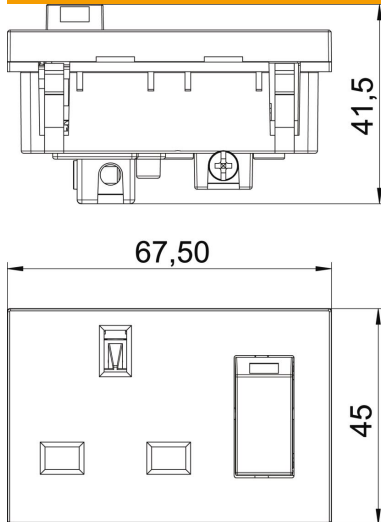

Width	67.5 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screw terminal
Number of units	1
Number of modules (for modular construction)	0
Number of switchable sockets	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Matt
Version for	British Standard
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Insulated installation	no
Hinged cover	no
Coding	no
Warning light	no
With on/off switch	yes
With fine-wire fuse	no
With functional lighting	no
With orientation lighting	no

Technical data sheet

0° socket with switch, British Standard, single

Item number: 6120724



Technical data

Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	13 A
ROHS-conformant	yes
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	41.5 mm
Transparent	no
Rotated central insert	no
Surge protection	no