

Technical data sheet

0° socket, South Africa/India, 16 A, encoded version, single

Item number: 6120732



Socket, single 0°, South Africa/India, encoded version, conforming to BS 546, with increased touch protection, with screw terminals, 2-pin, 16 A, 250 V~.



PC Polycarbonate

Master data	
Item number	6120732
Type	STD-SA0K SRO1
Description 1	Socket 0°, single, coded
Description 2	South Africa/India
Manufacturer	OBO
Dimension	250V, 16A
Colour	Signal red; RAL 3001
Material	Polycarbonate
Smallest sales unit	1
Unit of quantity	Piece
Weight	5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0097 kg CO2e / 1 Piece


Technical data sheet

0° socket, South Africa/India, 16 A, encoded version, single

Item number: 6120732



Dimensions

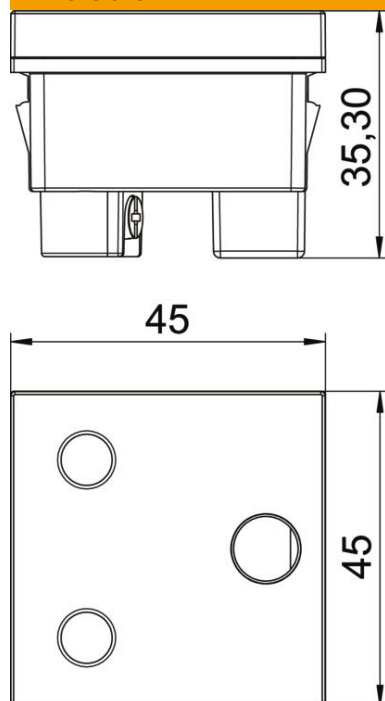

Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	South Africa/India
Fastening type	Lock
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
For more difficult conditions (according to VDE)	no
Coding	yes
With on/off switch	no
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
ROHS-conformant	yes
Protection rating	Other

Technical data sheet

0° socket, South Africa/India, 16 A, encoded version, single

Item number: 6120732



Technical data

Special power supply	Without special power supply
Transparent	no