


Technical data sheet

0° socket with switch, South Africa/India, 16 A, encoded version, single
Item number: 6120736

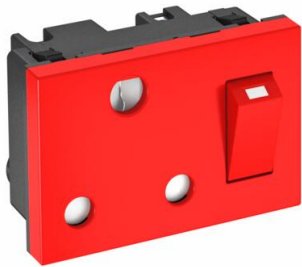

Socket, single 0°, with switch, South Africa/India, encoded version, conforming to BS 546, with increased touch protection, with screw terminals, 2-pin, 16 A, 250 V~.



PC Polycarbonate


Master data		
Item number	6120736	
Type	STD-SA0GK SRO1.5	
Description 1	Socket 0°, single, coded	
Description 2	South Africa/India, w. switch	
Manufacturer	OBO	
Dimension	250V, 16A	
Colour	Signal red; RAL 3001	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	6.7 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0186 kg CO2e / 1 Piece	

Technical data sheet

0° socket with switch, South Africa/India, 16 A, encoded version, single
Item number: 6120736



Dimensions

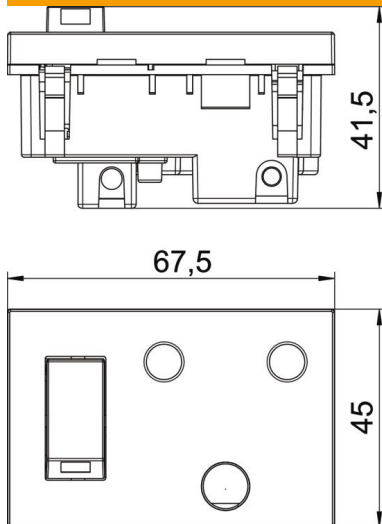

Technical data

Cover	Central plate
Closable	no
Number of units	1
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Not applicable
Version for	South Africa/India
Fastening type	Lock
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
For more difficult conditions (according to VDE)	no
Coding	yes
With on/off switch	yes
With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
ROHS-conformant	yes
Protection rating	Other
Special power supply	Without special power supply
Transparent	no