

Technical data sheet

0° socket, China, 16 A, single

Item number: 6120742



Socket, single 0°, China, with increased touch protection, with screw terminals, 2-pin,

16 A, 250 V~.



PC Polycarbonate

Master data		
Item number	6120742	
Type	STD-CN0A16 RW1	
Description 1	Socket 0°, single	
Description 2	China, 16A	
Manufacturer	OBO	
Dimension	250V, 16A	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	4.1 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,068 kg CO2e / 1 Piece	


Technical data sheet

0° socket, China, 16 A, single

Item number: 6120742



Dimensions

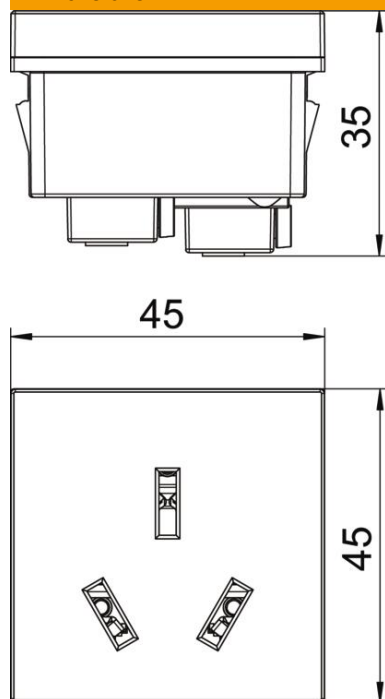

Width	45 mm
Height	45 mm

Technical data

Cover	Central plate
Closable	no
Connection type	Screw terminal
Number of units	1
Number of switchable sockets	0
Number of poles	2
Printed label/coding	Without printing
Version for	Single 0°
Surface version	Matt
Version for	Miscellaneous
Ejection mechanism	no
Fastening type	Lock
Labelling panel	no
Operating temperature, max.	40 °C
Operating temperature, min.	-5 °C
increased touch protection	yes
Error current protection	no
For more difficult conditions (according to VDE)	no
Halogen-free	yes
Hinged cover	no
Warning light	no
With on/off switch	no
With fine-wire fuse	no

Technical data sheet

0° socket, China, 16 A, single

Item number: 6120742



Technical data

With functional lighting	no
With orientation lighting	no
Mounting type	Device installation duct
Nominal voltage	250 V
Nominal current	16 A
ROHS-conformant	yes
Protection rating	Other
Special power supply	Without special power supply
Socket angle	0°
Depth	35 mm
Transparent	no
Rotated central insert	no
Surge protection	no