

Technical data sheet

Cover SLL 2050

Item number: 6132157



Cover for the skirting trunking.
As a cover for the trunking base. Snaps on to the trunking base.



PVC Polyvinylchloride

Master data

Item number	6132157
Type	SLL 2050 cws
Description 1	Cover
Description 2	SLL 20x50 9001
Manufacturer	OBO
Dimension	2000x20x16
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	18.2 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,3561 kg CO2e / 1 Meter


Technical data sheet

Cover SLL 2050

Item number: 6132157



Dimensions

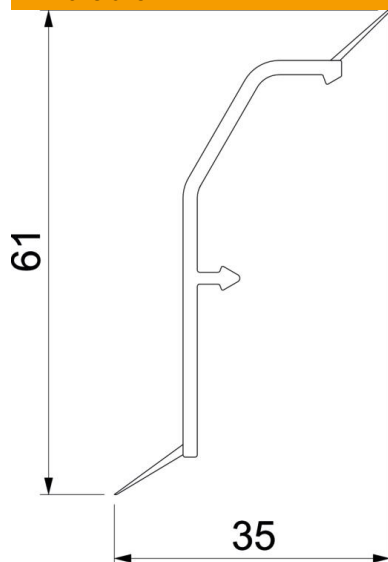

Length	2,000 mm
Width	50 mm
Height	20 mm

Technical data

Cover sealing lip	Wall/floor
ROHS-conformant	yes
Protection rating	IP40
Protection rating IK code	IK06
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C