

Technical data sheet

End piece SL ESre2050

Item number: 6132277



End piece (right) as a fitting for the skirting trunking.
For a clean end to the trunking system. For attaching to the trunking ends.



PVC Polyvinylchloride

Master data		
Item number	6132277	
Type	SL ESre2050 rws	
Description 1	End piece right	
Description 2	SL 20x50 9010	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	10	
Unit of quantity	Piece	
Weight	0.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0223 kg CO2e / 1 Piece	


Technical data sheet

End piece SL ESre2050


Item number: 6132277



Dimensions

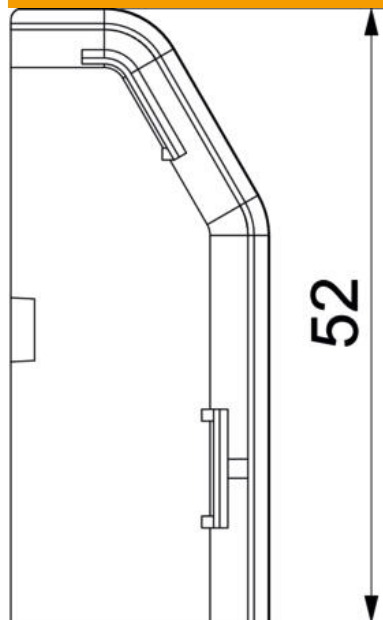

Length	22 mm
Width	18 mm
Height	52 mm

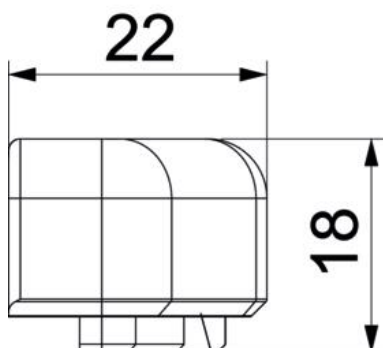

Technical data sheet

End piece SL ESre2050

Item number: 6132277



Technical data

Version for	Right
Decoration	Without
Cover sealing lip	Without
Halogen-free	no
With carpet strip	no
ROHS-conformant	yes
Protection rating	IP40
Protection rating IK code	IK06
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Pre-markings	no