

Technical data sheet

End piece SL ESre2070

Item number: 6132282



End piece (right) as a fitting for the skirting trunking.
For a clean end to the trunking system. For attaching to the trunking ends.



PVC Polyvinylchloride

Master data

Item number	6132282
Type	SL ESre2070 cw
Description 1	End piece right
Description 2	SL 20x70 9001
Manufacturer	OBO
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.69 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0257 kg CO2e / 1 Piece


Technical data sheet

End piece SL ESre2070


Item number: 6132282



Dimensions

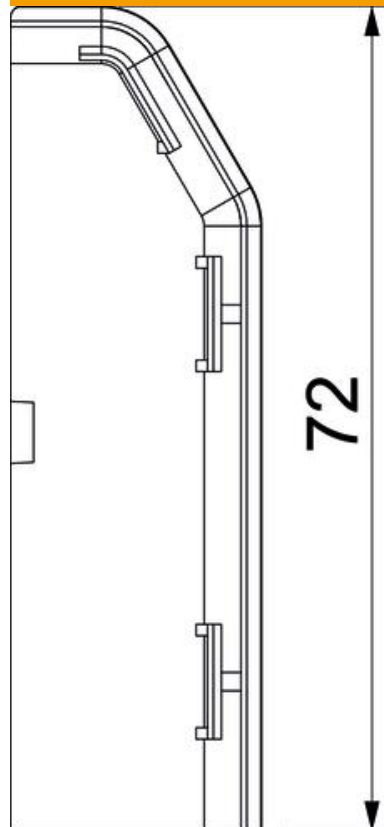

Length	22 mm
Width	18 mm
Height	72 mm

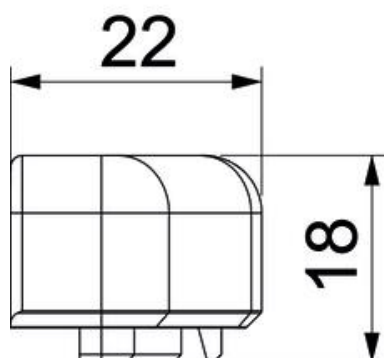

Technical data sheet

End piece SL ESre2070

Item number: 6132282



Technical data

Version for	Right
Decoration	Without
Cover sealing lip	Without
Halogen-free	no
With carpet strip	no
Protection rating	IP40
Protection rating IK code	IK06
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C
Pre-markings	no