

# Technical data sheet

## Device support SL GT5070M45

Item number: 6134500



Empty device support for the skirting trunking systems SL, SL-L and SL-T to install devices of module 45 design in the trunking widths 50 and 70 mm. When data modules are used, due to their design, compliance with the mandatory bending radius of the data cables is potentially not guaranteed.



**PVC** Polyvinylchloride

### Master data

|                                    |                               |
|------------------------------------|-------------------------------|
| Item number                        | 6134500                       |
| Type                               | SL GT5070M45 rws              |
| Description 1                      | Mounting box                  |
| Description 2                      | SL double 50/70 Modul 45 9010 |
| Manufacturer                       | OBO                           |
| Dimension                          | 116x139x50                    |
| Colour                             | Pure white; RAL 9010          |
| Material                           | Polyvinylchloride             |
| Smallest sales unit                | 1                             |
| Unit of quantity                   | Piece                         |
| Weight                             | 12.4 kg                       |
| Weight unit                        | kg/100 pc.                    |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,4215 kg CO2e / 1 Piece      |


# Technical data sheet

Device support SL GT5070M45

Item number: 6134500



## Dimensions

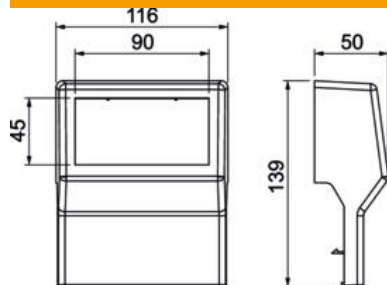

|        |        |
|--------|--------|
| Length | 116 mm |
| Width  | 139 mm |
| Height | 50 mm  |

## Technical data

|                                   |            |
|-----------------------------------|------------|
| Equipment                         | Without    |
| Decoration                        | Without    |
| for trunking height               | 70 mm      |
| Halogen-free                      | no         |
| Trunking height, max.             | 70 mm      |
| Duct height, min.                 | 50 mm      |
| Accessory mounting type           | Standard   |
| Mounting direction                | Horizontal |
| ROHS-conformant                   | yes        |
| Protection rating                 | IP40       |
| Protection rating IK code         | IK06       |
| Permitted temperature range, max. | 60 °C      |
| Permitted temperature range, min. | -5 °C      |