

Technical data sheet

T piece, for trunking type WDK 80210

Item number: 6163096



T piece to change the direction of the WDK trunking.



PVC Polyvinylchloride

Master data

Item number	6163096
Type	WDK T80210LGR
Description 1	T piece
Manufacturer	OBO
Dimension	400x210x80
Colour	Light grey; RAL 7035
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	130 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,8683 kg CO2e / 1 Piece


Technical data sheet

T piece, for trunking type WDK 80210

Item number: 6163096



Dimensions

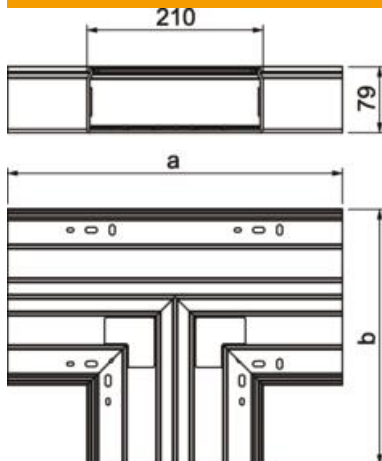

Length	400 mm
Width	210 mm
Height	80 mm
Dimension a	400 mm

Technical data

Version for	Base
Fastening type	Base perforation
Halogen-free	no
Protection rating	IP30
Protective film	no
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C