

Technical data sheet

Partition, halogen-free, for trunking height 40 mm

Item number: 6175500



Partition to divide the WDKH trunking of 40 mm trunking height for the installation of different voltage levels.
The partitions are pinned on the connectors in the base.



PC/
ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175500
Type	WDKH-TW40LGR
Description 1	Partition
Description 2	halogen-free
Manufacturer	OBO
Dimension	15x28x2000
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Metre
Weight	13.35 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,7815 kg CO2e / 1 Meter


Technical data sheet

Partition, halogen-free, for trunking height 40 mm

Item number: 6175500



Dimensions

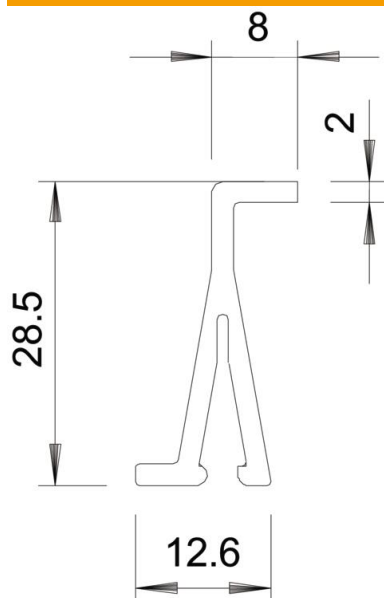

Length	2,000 mm
Width	12.6 mm
Height	28.5 mm
Dimension a	2,000 mm

Technical data

Version for	Single
Fastening type	Lockable
Halogen-free	yes
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK07
Self-extinguishing	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C