

Technical data sheet

End piece, trunking type WDKH 40060

Item number: 6175558



End piece for closing the WDK-H trunking.
The end pieces are pushed onto the WDK trunking and are fixed on the connector by spring force.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175558
Type	WDKH-E40060RW
Description 1	End piece
Description 2	halogen-free
Manufacturer	OBO
Dimension	40x60mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.992 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0866 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDKH 40060

Item number: 6175558



Dimensions

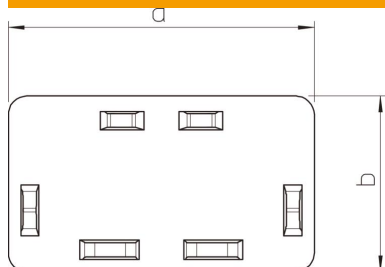

Length	27.5 mm
Width	60 mm
Height	40 mm
Dimension a	40 mm
Dimension b	60 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
ROHS-conformant	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C