

Technical data sheet

Flat angle cover, trunking type WDKH 40060

Item number: 6175666



Flat angle hood for changing the direction of the halogen-free WDKH trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175666
Type	WDKH-F40060RW
Description 1	Flat angle cover
Description 2	halogen-free
Manufacturer	OBO
Dimension	40x60mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Piece
Weight	7.048 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,415 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDKH 40060

Item number: 6175666



Dimensions

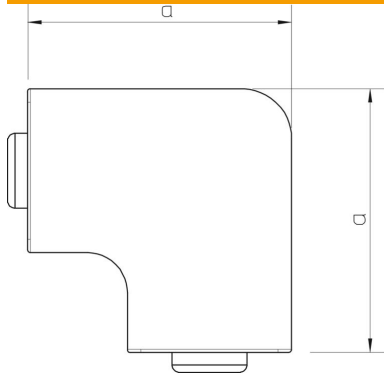

Length	101 mm
Width	65 mm
Height	40 mm
Dimension a	85 mm
Dimension H	60 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	40 x 60
Halogen-free	yes
Duct height, min.	60 mm
Trunking depth	40 mm
ROHS-conformant	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Self-extinguishing	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm