

# Technical data sheet

## Flat angle cover, trunking type WDKH 60110

Item number: 6175674



Flat angle hood for changing the direction of the halogen-free WDKH trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

### Master data

|                                    |                                              |
|------------------------------------|----------------------------------------------|
| Item number                        | 6175674                                      |
| Type                               | WDKH-F60110RW                                |
| Description 1                      | Flat angle cover                             |
| Description 2                      | halogen-free                                 |
| Manufacturer                       | OBO                                          |
| Dimension                          | 60x110mm                                     |
| Colour                             | Pure white; RAL 9010                         |
| Material                           | Polycarbonate/Acrylnitrile-butadiene-styrene |
| Smallest sales unit                | 2                                            |
| Unit of quantity                   | Piece                                        |
| Weight                             | 12.984 kg                                    |
| Weight unit                        | kg/100 pc.                                   |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,7578 kg CO2e / 1 Piece                     |


# Technical data sheet

## Flat angle cover, trunking type WDKH 60110

Item number: 6175674



### Dimensions

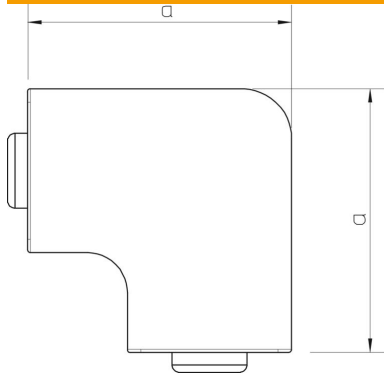

|             |        |
|-------------|--------|
| Length      | 149 mm |
| Width       | 110 mm |
| Height      | 60 mm  |
| Dimension a | 149 mm |

### Technical data

|                                   |              |
|-----------------------------------|--------------|
| Version for                       | Hood fitting |
| Fastening type                    | Lockable     |
| Maintain electrical functions     | no           |
| for duct dimension                | 60 x 110     |
| Halogen-free                      | yes          |
| Trunking depth                    | 60 mm        |
| ROHS-conformant                   | yes          |
| Protection rating                 | IP30         |
| Protective film                   | no           |
| Protection rating IK code         | IK07.        |
| Self-extinguishing                | yes          |
| Permitted temperature range, max. | 90 °C        |
| Permitted temperature range, min. | -5 °C        |
| Angle range, max.                 | 90 mm        |
| Angle range, min.                 | 90 mm        |