

Technical data sheet

End piece, trunking type WDKH 60150

Item number: 6175948



End piece for closing the WDK-H trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6175948
Type	WDKH-E60150LGR
Description 1	End piece
Description 2	halogen-free
Manufacturer	OBO
Dimension	60x150mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	3.736 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2814 kg CO2e / 1 Piece


Technical data sheet

End piece, trunking type WDKH 60150

Item number: 6175948



Dimensions

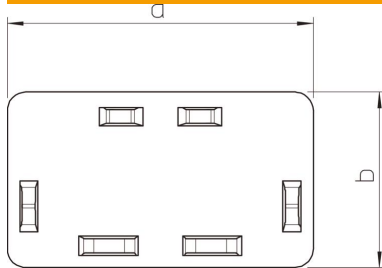

Length	27.5 mm
Width	150 mm
Height	60 mm
Dimension a	150 mm
Dimension b	60 mm

Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK07.
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C