

Technical data sheet

Flat angle cover, trunking type WDKH 60090

Item number: 6176048



Flat angle hood for changing the direction of the halogen-free WDKH trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6176048
Type	WDKH-F60090LGR
Description 1	Flat angle cover
Description 2	halogen-free
Manufacturer	OBO
Dimension	60x90mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Piece
Weight	9.696 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,6039 kg CO2e / 1 Piece


Technical data sheet

Flat angle cover, trunking type WDKH 60090

Item number: 6176048



Dimensions

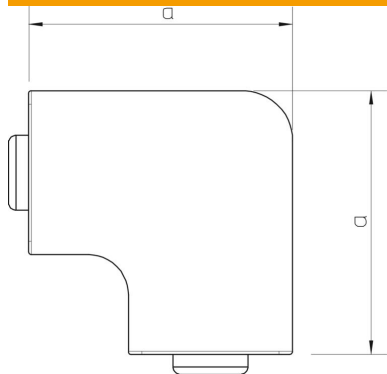

Length	129 mm
Width	94 mm
Height	60 mm
Dimension a	129 mm

Technical data

Version for	Hood fitting
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
Trunking depth	60 mm
ROHS-conformant	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK07.
Self-extinguishing	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm