


Technical data sheet

Cover clip for WDKH trunking, trunking width 60 mm

Item number: 6176122



Cover clip for better and easier laying of lines in the WDKH trunking.

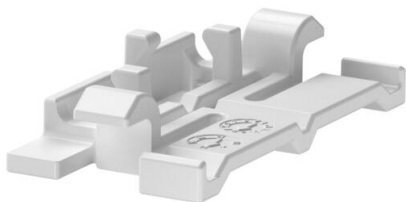

PC/ABS Polycarbonate/Acrylnitrile-butadiene-styrene

Master data	
Item number	6176122
Type	OTK H60
Description 1	Cover fixing device
Description 2	halogen-free
Manufacturer	OBO
Dimension	49x29
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0362 kg CO2e / 1 Piece


Technical data sheet

Cover clip for WDKH trunking, trunking width 60 mm

Item number: 6176122



Dimensions

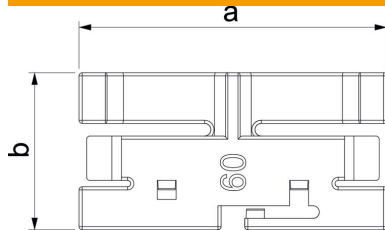

Length	24.8 mm
Width	48.8 mm
Height	10 mm
Dimension a	48.8 mm
Dimension b	24.8 mm

Technical data

Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
With equipotential bonding	no
Cover width	60 mm
Protection rating	IP30
Protection rating IK code	IK07.
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C