


Technical data sheet

Clamping piece LKS 40 FS

Item number: 6221076

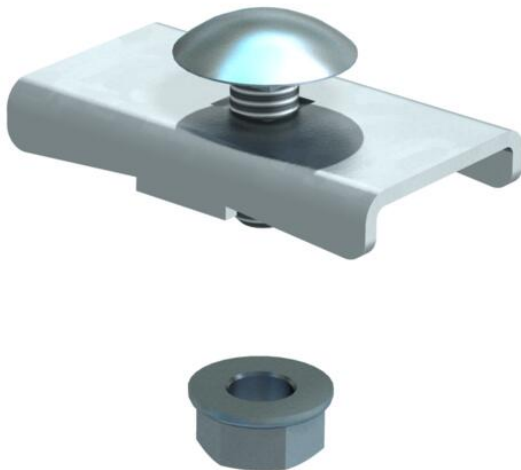

Clamping piece for fastening cable ladders of side height 60 mm to wall or support brackets.

Fastening on brackets, type MWA 12, AW 15, AW 30 and AW 55, using the enclosed truss-head bolt FRS M6 x 20.

Including appropriate truss-head bolts and combination nuts.



St

Steel

FS

Strip galvanised

Master data

Item number	6221076
Type	LKS 40 FS
Description 1	Hold-down clamp
Description 2	for cable ladder LG60
Manufacturer	OBO
Dimension	40x22
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0644 kg CO2e / 1 Piece


Technical data sheet

Clamping piece LKS 40 FS

Item number: 6221076



Dimensions

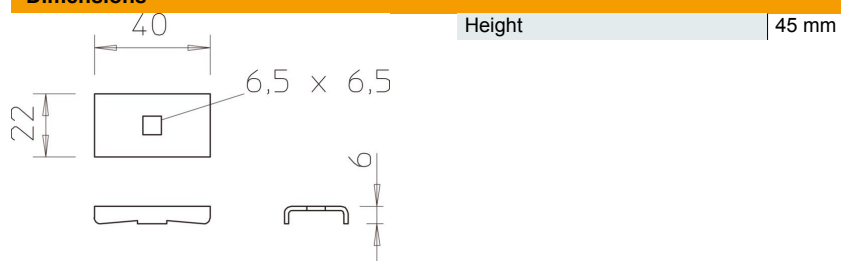

Technical data

ROHS-conformant	yes
-----------------	-----