

Technical data sheet

Joint connector LKM SV30

Item number: 6247434



Joint connector to connect the bases. This creates the equipotential bonding between the duct bases.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6247434
Type	LKM SV30
Description 1	Joint connector
Manufacturer	OBO
Dimension	30mm
Colour	stainless steel
Material	Stainless steel 1.4310
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	0.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0542 kg CO2e / 1 Piece


Technical data sheet

Joint connector LKM SV30

Item number: 6247434



Dimensions

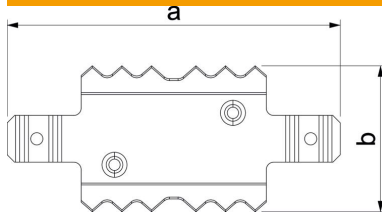

Width	30 mm
Dimension a	54 mm
Dimension b	30 mm

Technical data

Version for	Inside
Maintain electrical functions	yes
for duct dimension	20 x 30
Halogen-free	yes
With equipotential bonding	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C