


Technical data sheet

External corner cover, smooth

Item number: 6274790



PVC external corner cover, smooth surface.

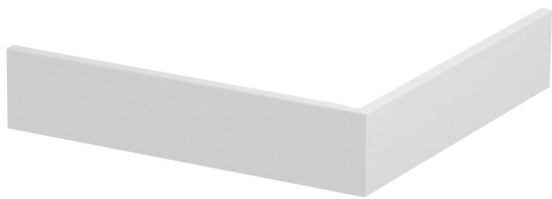

Master data		
Item number	6274790	
Type	GK-OTGARW	
Description 1	Cover	
Description 2	external corner, smooth	
Manufacturer	OBO	
Colour	Pure white; RAL 9010	
Material	Polyvinylchloride	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	9.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,4241 kg CO2e / 1 Piece	


Technical data sheet

External corner cover, smooth

Item number: 6274790



Dimensions

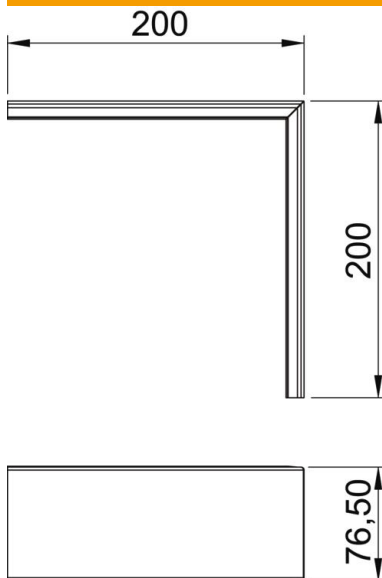

Length	200 mm
Width	76.5 mm
Height	12 mm

Technical data

Application	External corner
Halogen-free	no
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C