


Technical data sheet

External corner cover, fluted

Item number: 6274890



PVC external corner cover, fluted surface.

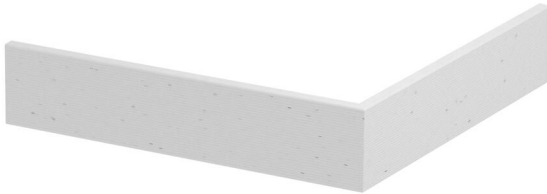

PVC Polyvinylchloride

Master data

Item number	6274890
Type	GK-OTKARW
Description 1	Cover
Description 2	external corner, fluted
Manufacturer	OBO
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Piece
Weight	10.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2667 kg CO2e / 1 Piece


Technical data sheet

External corner cover, fluted

Item number: 6274890



Dimensions

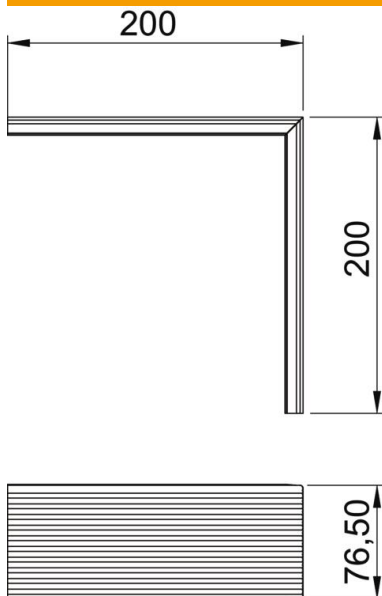

Length	200 mm
Width	76.5 mm

Technical data

Application	External corner
Halogen-free	no
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C