

Technical data sheet

Partition GS-TW70

Item number: 6277090



Partition to divide the trunking for different voltage levels. Self-conducting contacting during mounting.



St	Steel
FS	Strip galvanised

Master data

Item number	6277090
Type	GS-TW70
Description 1	Partition
Description 2	for GS 70
Manufacturer	OBO
Dimension	24x53x2000
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	58.65 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,3095 kg CO2e / 1 Meter


Technical data sheet

Partition GS-TW70

Item number: 6277090



Dimensions

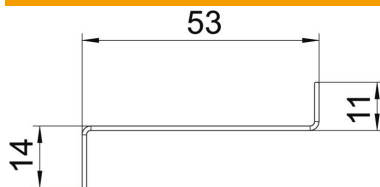

Length	2,000 mm
Width	24 mm
Height	53 mm

Technical data

Version for	Single
Fastening type	Plug-in
Suitable for duct depth	70
Halogen-free	yes
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C