

Technical data sheet

Coupling GS-KUP70

Item number: 6277290



Coupling for connecting the trunking bases. This creates the equipotential bonding between the trunking bases.

The scope of delivery of a coupling includes 2 connection plates.



A2 Stainless steel

Master data

Item number	6277290
Type	GS-KUP70
Description 1	Coupling
Description 2	universal, f. trunking depth 70
Manufacturer	OBO
Dimension	70x120
Colour	stainless steel
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Packaging unit
Weight	6.4 kg
Weight unit	kg/100 PUs
CO2 Footprint (GWP) Cradle-to-Gate	0,3421 kg CO2e / 2 Piece


Technical data sheet

Coupling GS-KUP70

Item number: 6277290



Dimensions

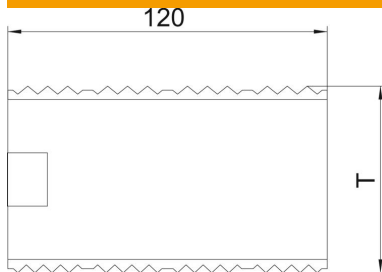

Length	120 mm
Width	70 mm

Technical data

Version for	Universal
Type	coupling
Halogen-free	yes
Trunking depth	70 mm
With equipotential bonding	yes
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C