

Technical data sheet


Coupling GS-KUP90

Item number: 6277294



Coupling for connecting the trunking bases. This creates the equipotential bonding between the trunking bases.

The scope of delivery of a coupling includes 2 connection plates.

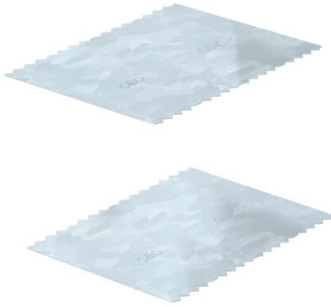

A2 Stainless steel

Master data

Item number	6277294
Type	GS-KUP90
Description 1	Coupling
Description 2	univ., for trunking depth 90
Manufacturer	OBO
Dimension	90x120
Colour	stainless steel
Material	Stainless steel 1.4301
Smallest sales unit	1
Unit of quantity	Packaging unit
Weight	8.2 kg
Weight unit	kg/100 PUs
CO2 Footprint (GWP) Cradle-to-Gate	0,4365 kg CO2e / 2 Piece


Technical data sheet

Coupling GS-KUP90

Item number: 6277294



Dimensions

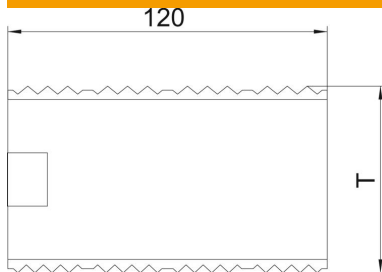

Length	120 mm
Width	90 mm

Technical data

Version for	Universal
Type	coupling
Halogen-free	yes
Trunking depth	90 mm
With equipotential bonding	yes
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C