

Technical data sheet

Plastic trunking cover, fluted

Item number: 6278780



Fluted trunking cover, for closing device installation trunking with 76.5 mm system opening.



PVC Polyvinylchloride

Master data

Item number	6278780
Type	GK-OTKRW
Description 1	Cover
Description 2	fluted
Manufacturer	OBO
Dimension	80x2000mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	27 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,5657 kg CO2e / 1 Meter


Technical data sheet

Plastic trunking cover, fluted

Item number: 6278780



Dimensions

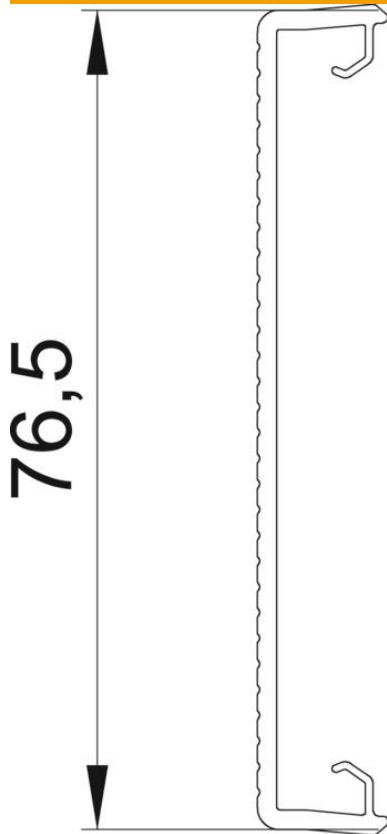

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Profiled
Halogen-free	no
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C