

Technical data sheet

Trunking cover Rapid 80, PC, clear, fluted inside

Item number: 6278790



Trunking cover for closing Rapid 80 GK (PVC), GS (steel) and GA (aluminium) device installation trunking as well as ISS service poles with a 76.5 mm system opening. The GK-OTKKP cover is made from clear, transparent plastic and the inside is fluted (longitudinal) and is therefore suitable for integrating lighting in the trunking and service pole.



PC Polycarbonate

Master data

Item number	6278790
Type	GK-OTKKPI
Description 1	Cover
Description 2	fluted clear Prisma inside
Manufacturer	OBO
Dimension	80x2000mm
Colour	Transparent
Material	Polycarbonate
Smallest sales unit	2
Unit of quantity	Metre
Weight	21.8 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,8038 kg CO2e / 1 Meter


Technical data sheet

Trunking cover Rapid 80, PC, clear, fluted inside

Item number: 6278790



Dimensions

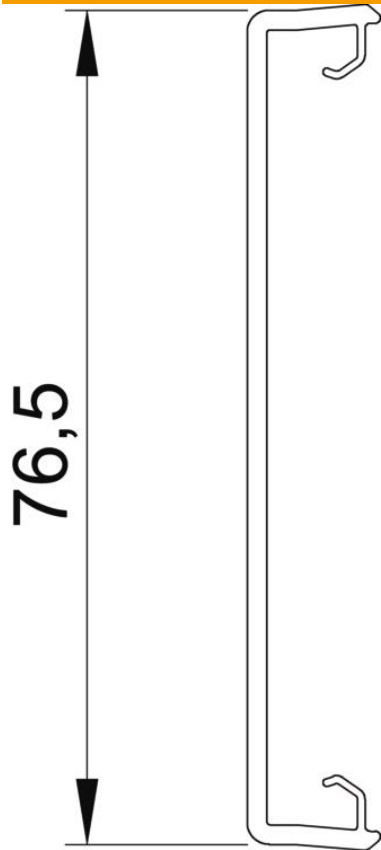

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Profiled
Halogen-free	no
Cover mounting type	Internal
ROHS-conformant	yes
Protective film	yes