

Technical data sheet


Partition GA-TW70

Item number: 6279711



Partition to divide the Rapid 80 GA, Rapid IBIS aluminium device installation trunking and ISS service poles for the installation of different voltage levels.

For vertical mounting of device installation trunking and the installation of ISS service poles, the duct clamps, type KL80A, are required for secure fixing of the partition.

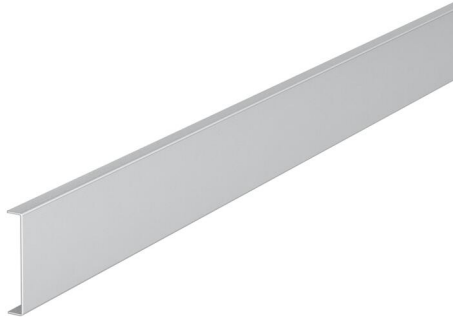

St

Steel

FS

Strip galvanised

Master data

Item number	6279711
Type	GA-TW70
Description 1	Partition
Description 2	for GA 70
Manufacturer	OBO
Dimension	8,4x51x2000
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	51.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,3854 kg CO2e / 1 Meter


Technical data sheet

Partition GA-TW70

Item number: 6279711



Dimensions

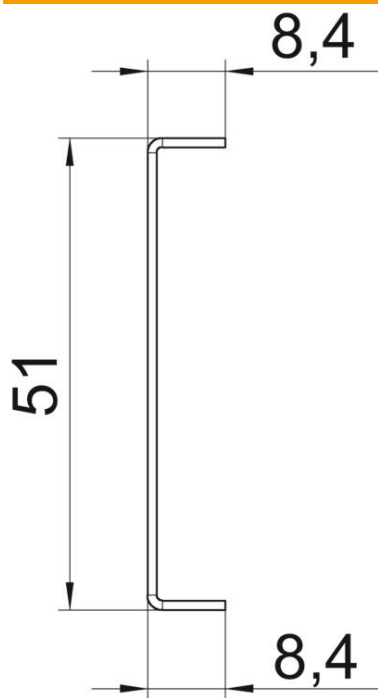

Length	2,000 mm
Width	51 mm
Height	8.4 mm

Technical data

Version for	Single
Fastening type	Insertable
Suitable for duct depth	70
Halogen-free	yes
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C