

Technical data sheet

Aluminium flat angle cover

Item number: 6279734



Flat angle cover for mounting on the Rapid 80 GA flat angle fitting.



Alu Aluminium

Master data

Item number	6279734
Type	GA-OTFRW
Description 1	Cover
Description 2	for flat angle
Manufacturer	OBO
Dimension	12x76,5x400
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	28.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,1605 kg CO2e / 1 Piece


Technical data sheet

Aluminium flat angle cover

Item number: 6279734



Dimensions

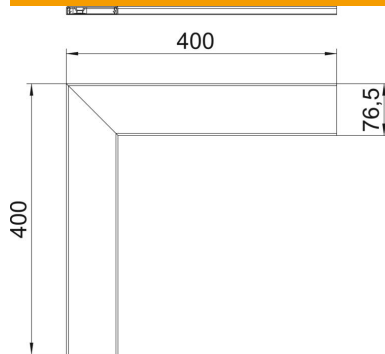

Length	400 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C