


Technical data sheet

Wall panel adapter KS70170 for GK plastic, trunking width 170 mm

Item number: 6279806



Wall panel adapter for mounting the GK70170 device installation trunking on fastening panels.

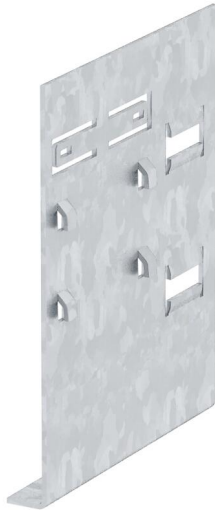

- St** Steel
- FS** Strip galvanised

Master data

Item number	6279806
Type	KS70170
Description 1	Wall bracket adapter
Description 2	for GK70170
Manufacturer	OBO
Dimension	128x162x27mm
Colour	zinc
Material	Steel
Surface	Strip galvanised
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	34.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,0468 kg CO2e / 1 Piece


Technical data sheet

Wall panel adapter KS70170 for GK plastic, trunking width
170 mm

Item number: 6279806



Dimensions

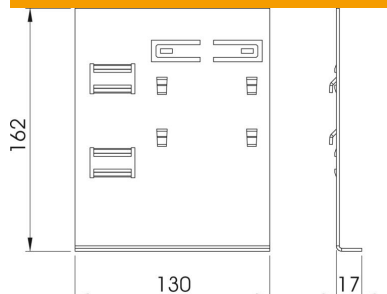

Length	130 mm
Width	162 mm
Height	17 mm

Technical data

Version for	Wall mounting
Fastening type	Lockable
for duct dimension	70x170 mm
ROHS-conformant	yes
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C