

Technical data sheet

Trunking cover, sheet steel

Item number: 6279850



Cover to close the device installation trunking GEK-S and GEK-A.



St Steel

Master data

Item number	6279850
Type	GS-OTRW
Description 1	Cover
Manufacturer	OBO
Dimension	12x76,5x2000
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	2
Unit of quantity	Metre
Weight	65 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,5158 kg CO2e / 1 Meter


Technical data sheet

Trunking cover, sheet steel

Item number: 6279850



Dimensions

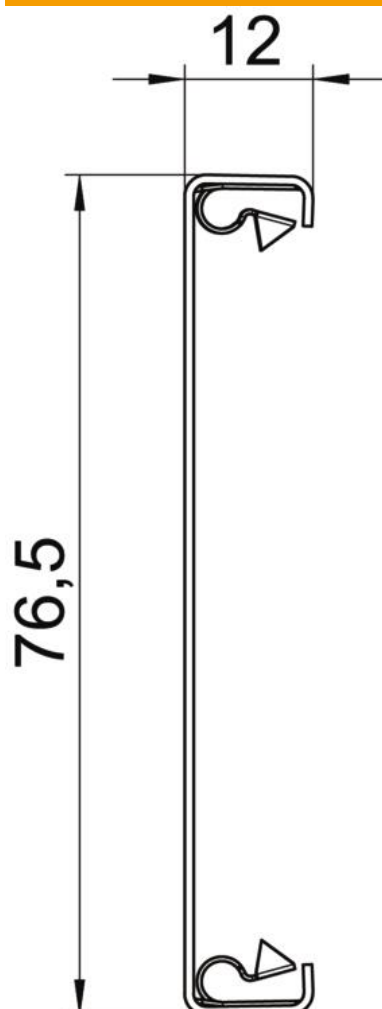

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C