


Technical data sheet

Sheet steel external corner cover

Item number: 6279870

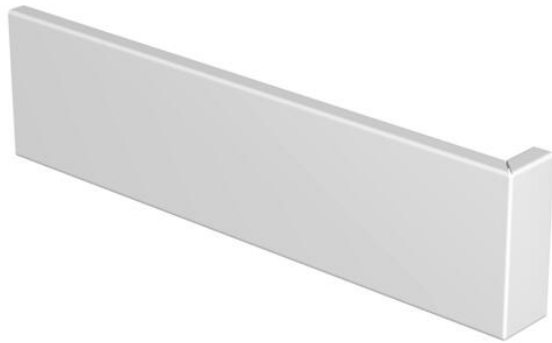

Cover to close the external corner of the Rapid 80 GS device installation trunking.



St Steel

Master data

Item number	6279870
Type	GS-OTARW
Description 1	Cover
Description 2	for external corner 80
Manufacturer	OBO
Dimension	12x76,5x300
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	21.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8952 kg CO2e / 1 Piece


Technical data sheet

Sheet steel external corner cover

Item number: 6279870



Dimensions

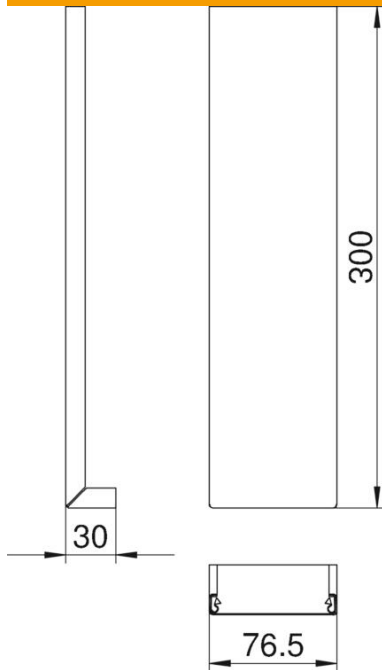

Length	300 mm
Width	76.5 mm
Height	12 mm

Technical data

Application	External corner
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C