


Technical data sheet

Panel 190 mm for ISSMKS

Item number: 6286760

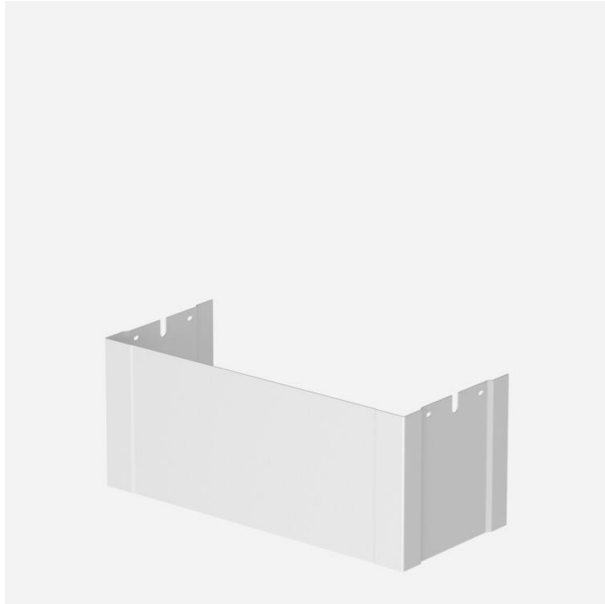

Height compensation panel for variable height adjustment. Hides the distance between the media pole and the ceiling. Suitable for a room height of 2,820 mm to 2,985 mm.



St	Steel
P	Powder-coated

Master data

Item number	6286760
Type	ISSMKS BL RW 190
Description 1	Height compensation panel
Description 2	for ISSMKS
Manufacturer	OBO
Dimension	190x461x201
Colour	Pure white; RAL 9010
Material	Steel
Surface	Powder-coated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	190.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	8,2942 kg CO2e / 1 Piece


Technical data sheet

Panel 190 mm for ISSMKS

Item number: 6286760



Dimensions

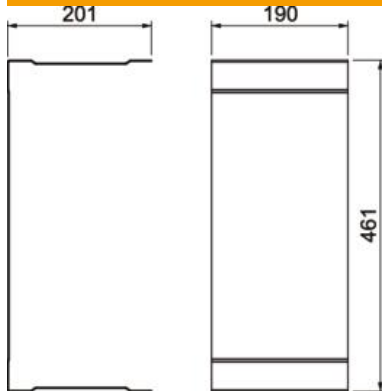

Length	190 mm
Width	461 mm
Height	201 mm

Technical data

Type of accessory	Miscellaneous
Fastening type	Bolts
Halogen-free	yes
Height compensation, min.	165 mm
ROHS-conformant	yes
Protection rating	IP20
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C