

Technical data sheet

Sheet steel internal corner cover

Item number: 6287080



Cover for closing internal corners.



St

Steel

Master data

Item number	6287080
Type	IOP3RW
Description 1	Cover
Description 2	for int corner desk trunking
Manufacturer	OBO
Dimension	12x76,5x300
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	20.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,1289 kg CO2e / 1 Piece


Technical data sheet

Sheet steel internal corner cover

Item number: 6287080



Dimensions

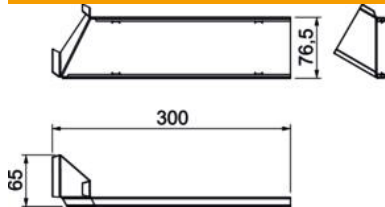

Length	300 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Halogen-free	yes
Cover mounting type	Internal
ROHS-conformant	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C