

Technical data sheet

Brush outlet

Item number: 6288638



Brush outlet for simple routing of cables out of the 76.5 mm system opening of Rapid 80 plastic and aluminium device installation trunking and ISS aluminium service poles. Any strain relief required is not contained in the scope of delivery.



PA/
GF

Polyamide, fibreglass reinforced

Master data		
Item number	6288638	
Type	BA80	
Description 1	Brush outlet	
Description 2	for 80 system opening	
Manufacturer	OBO	
Dimension	48x78x12	
Colour	Black	
Material	Polyamide, fibreglass reinforced	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.4 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1514 kg CO2e / 1 Piece	


Technical data sheet

Brush outlet

Item number: 6288638



Dimensions

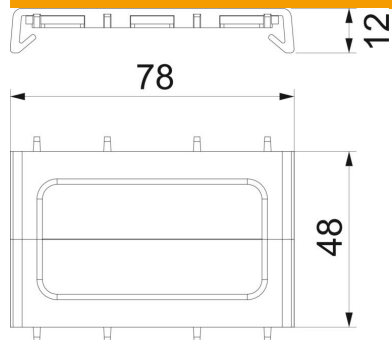

Length	48 mm
Width	78 mm
Height	12 mm

Technical data

Cover width	76.5 mm
ROHS-conformant	yes