

Technical data sheet

Locking bracket RKV3V

Item number: 6288700



Locking bracket for the mechanical and electrical connection of trunking covers and trunking bases. Suitable for covers of Rapid 45, Rapid 80 and ISS systems. When making cover cut-outs, observe the following minimum quantities.

L<1,000 mm: 4 units

L=1,000–2,000 mm: 6 units

L>2,000 mm: 8 units



St Steel

G Electrogalvanised

Master data

Item number	6288700
Type	RKV3V
Description 1	Locking bracket
Description 2	for GS/GA
Manufacturer	OBO
Dimension	11x20x6
Colour	zinc
Material	Steel
Surface	Electrogalvanised
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	20
Unit of quantity	Piece
Weight	0.085 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0075 kg CO2e / 1 Piece


Technical data sheet

Locking bracket RKV3V

Item number: 6288700



Dimensions

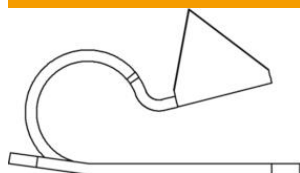

Length	11 mm
Width	20 mm
Height	6 mm

