

Technical data sheet

Service pole, type ISS140110

Item number: 6288960



ISS aluminium service pole with a 76.5 mm system opening.

Set consists of:

1 two-compartment pole with clamping fastening

Total length 3,315–3,480 mm

1 ceiling fastening with clamping device

2 aluminium covers

Length: 3,000 mm

The service pole is suitable for accepting front-locking accessory mounting boxes of the series 71GD... The installation of a partition of type GA-TW70 (6279711) and the installation of the cover clip, type KL80A (6288640), are possible as an option.

The following accessories can be used, depending on the mounting situation.



Alu Aluminium

Master data

Item number	6288960
Type	ISS140110RW
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	3000x110x140
Colour	Pure white; RAL 9010
Material	Aluminium
Smallest sales unit	1
Unit of quantity	Piece
Weight	1370 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	193,6366 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISS140110

Item number: 6288960



Dimensions

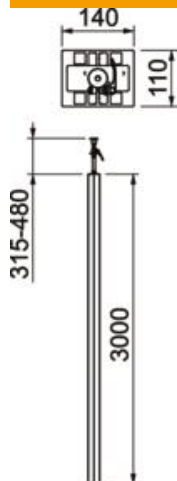

Length	3,000 mm
Width	110 mm
Height	140 mm

Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	yes
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no