

Technical data sheet

Service pole, type ISS140100R

Item number: 6289073



ISS aluminium service pole with a thin tube to the ceiling.

Set consists of:

1 two-compartment pole with clamping fastening

Total length 3,315–3,480 mm

1 ceiling fastening with clamping device

2 aluminium covers

Length: 780 mm

The service pole has a 76.5 mm system opening in the area for device installation and is suitable for accepting front-locking accessory mounting boxes of the series 71GD...



Alu Aluminium

EL Anodised

Master data

Item number	6289073
Type	ISS140100REL
Description 1	Service pole
Description 2	floor/ceiling
Manufacturer	OBO
Dimension	3000x100x140
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	1390 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	158,8257 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISS140100R

Item number: 6289073



Dimensions

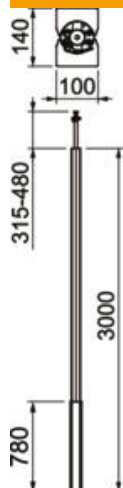

Length	3,000 mm
Width	100 mm
Height	140 mm

Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Tension
Floor mounting	yes
Ceiling mounting	yes
Continuous profile	no
Halogen-free	yes
Height compensation, max.	480 mm
Height compensation, min.	315 mm
Cable entry	Top/bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Installation space, angular/pole, round
Pole height, max.	3480 mm
Pole height, min.	3315 mm
Adjustable	yes
Pre-wired	no